



- Type**
- SC** With key (same lock)
 - SU** With key (different lock)
 - SCK** With wing knob (same lock)
 - SUK** With wing knob (different lock)
 - SCT** With T-Handle (same lock)
 - SUT** With T-Handle (different lock)
 - LCG** With Hand lever (only in SW) (same lock)
 - LUG** With Hand lever (only in SW) (different lock)


Type LCG / LUG

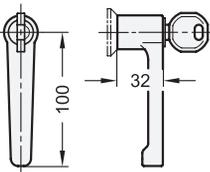

Type SCT / SUT

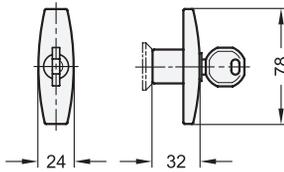

Type SCK / SUK

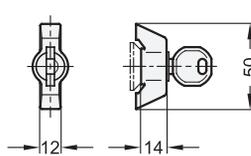

2

Latch arm distance A											d		h	
4	8	13	16	20	24	28	32	36	40	45	Type SC, SU	Type SCK, SUK, SCT, SUT, LCG, LUG	Type SC, SU	Type SCK, SUK, SCT, SUT, LCG, LUG
4	8	13	16	20	24	28	32	36	40	45	28	32	4	6
6	10	14	18	22	26	30	34	38	42	50	28	32	4	6

Specification

3

- Lock housing
Zinc die casting
 - Housing collar, chrome plated —
 - Housing collar, powder coated Black, RAL 9005, textured finish ● SW
- Operating elements
 - Type SCK / SUK / SCT / SUT
Plastic (Polyamide PA)
Black, matte finish
 - Type LCG / LUG
Zinc die casting
Powder coated
Black, RAL 9005, textured finish
- Key
Nickel silver with plastic hand piece
- Other parts
Steel, zinc plated, blue passivated
- Protection class IP65
Type SCK / SUK / SCT / SUT / LCG / LUG
- IP Protection Classes → Page 2153
- Plastic Characteristics → Page 2158
- RoHS

Information

Lockable latches GN 115 lock by a turning operation limited to 90° which moves the latch arm in the locked position behind the door frame. The bevels of the latch arm ease the closing of the door.

Latch arms are available with different bend angles to cover a latch arm distance A from 4 to 50 mm.

The latches are delivered with 2 keys and loosely enclosed latch arm. The key can be removed in both end positions.

Types with a standard lock allow every lock to be opened with the same key. For the types with different lock, there are more than 200 different lock variants, whose keys are marked by numbers.

see also...

• Construction and Assembly Instructions → Page 1201

How to order (Housing collar, chrome plated)	1	Type
GN 115-SC-42	2	Latch arm distance A

How to order (Housing collar, black)	1	Type
GN 115-SU-18-SW	2	Latch arm distance A
	3	Finish

3.1
3.2
3.3
3.4
3.5
3.6
3.7
3.8
3.9