


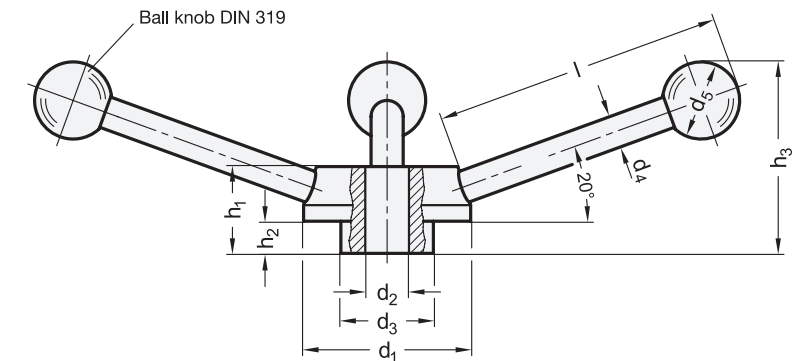

- 2


Bore code
- B

Without keyway
- K

With keyway DIN 6885-1 P9
- V

With square DIN 79

Bore code

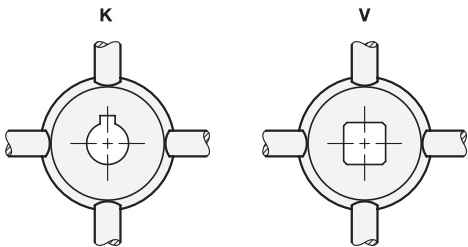

1 d₁	3 d₂ Bore H7 Square H11	d ₃	d ₄	d ₅	h ₁	h ₂	h ₃ ≈	Length l ≈
50	12	28	8	20	26	9	53	82
55	14	30	10	25	28	10	61	96
60	15	32	10	25	30	11	64	96
65	16	35	12	30	32	12	71	110
72	18	40	12	32	36	14	80	124
80	20	44	14	35	40	16	89	138
100	24	54	16	40	52	24	113	170

Specification

Hub / Shafts

Steel
Blackened

Ball knobs DIN 319

Plastic, phenolic resin (PF)
Black, shiny finish

RoHS

Technical Information

	Page
Keyways DIN 6885-1	QVX
Squares DIN 79	QVX
ISO Fundamental Tolerances	QVX
Plastic Characteristics	QVX

How to order	1 d ₁
1 2 3 GN213-65-B16	2 Bore code
	3 d ₂