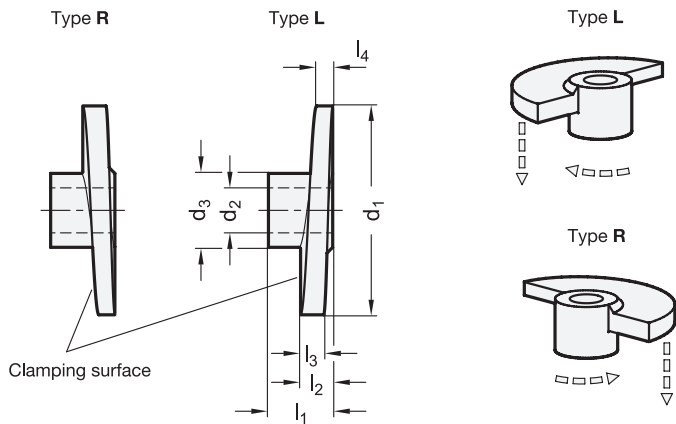


- 4

Type
- L Clamping direction
left turn
- R Clamping direction
right turn

d ₁	d ₂ H8		d ₃	l ₁ ≈	l ₂	l ₃	l ₄
35	B 8	B 10	18	15	7	7	3
65	B 12	-	23	20	10	7	5
80	B 16	-	27	24	12	9	6

Specification

1

SM

- Steel
- Sintered
- Black oxidized with vapor
- ISO Fundamental Tolerances → Page 2151
- RoHS

Information

see also...

- Latches GN 118 (Complete Kits) → Page 1244

How to order

1

2

3

4

GN218-SM-35-B10-L

1	Material
2	d ₁
3	d ₂
4	Type