


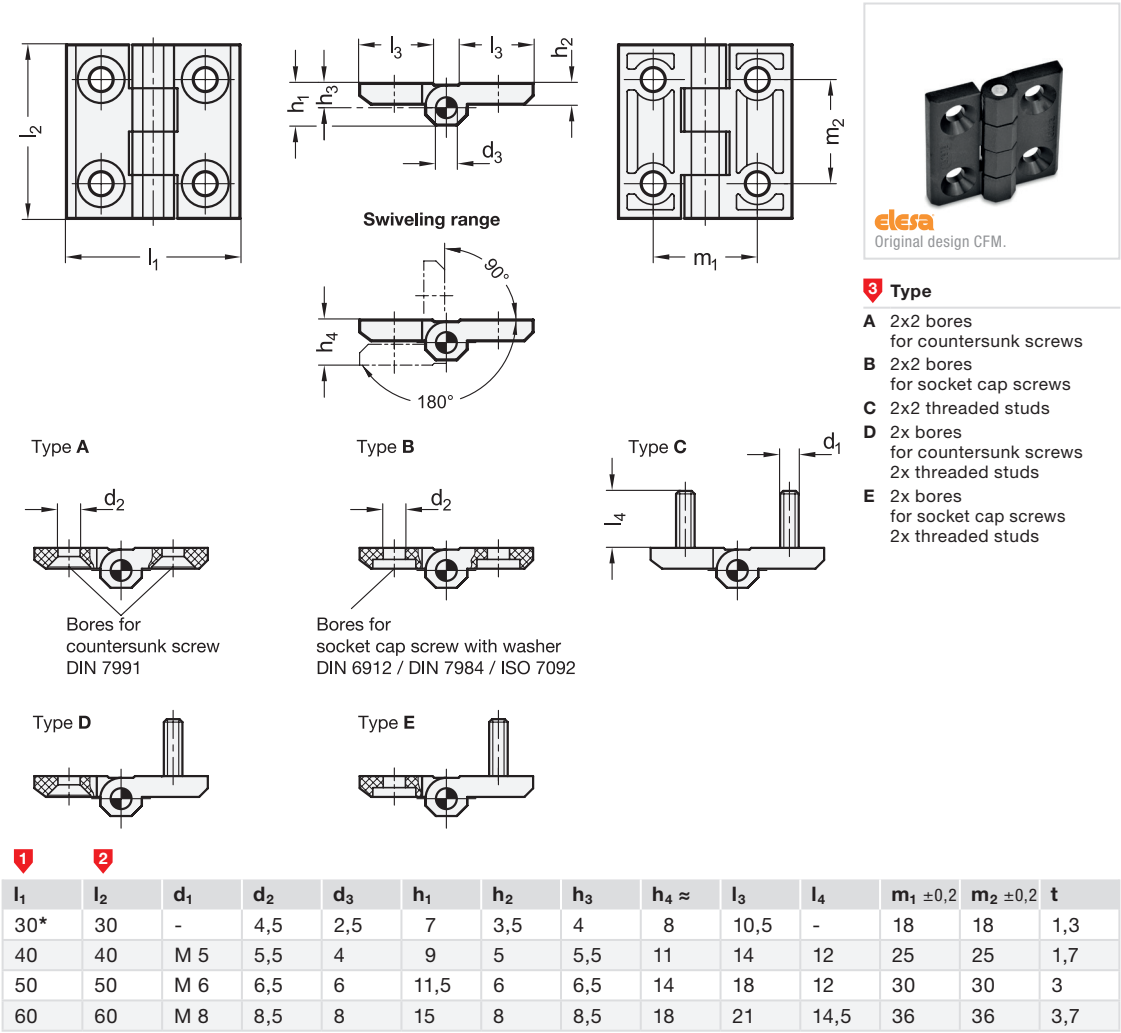

*only available in type A and type B

4

Specification

- Plastic (Polyamide PA)
 - Glass fiber reinforced
 - Temperature resistant up to 140 °C
 - Black, matte finish
 - White, RAL 9002, matte finish (only type A)
- Pin
 - Stainless steel AISI 303
- Threaded studs
 - Steel, nickel plated
- Load Rating Information → Page 2126
- Plastic Characteristics → Page 2158
- Stainless Steel Characteristics → Page 2166
- RoHS

4

Information

see also...

- List of Hinge Types → Page 1284 ff.
- Hinges GN 237 (Zinc Die Casting / SST / Aluminum) → Page 1292
- Hinges GN 337.1 (Detachable) → Page 1379
- Stainless Steel Spacer Plates GN 2370 → Page 1350
- Stainless Steel Plates with Tapped Holes GN 2372 → Page 1351
- Rubber Bumper Stops GN 2374 → Page 1298

How to order (Black)

1

2

3

GN 237.1-40-40-C

1

2

3

1

 l_1

2

 l_2

3

Type

How to order (White)

1

2

3

4

GN 237.1-50-50-A-WS

1

2

3

4

1

 l_1

2

 l_2

3

Type

4

Color