


**elesa**  
Original design TCC-A / TCC-A-Q

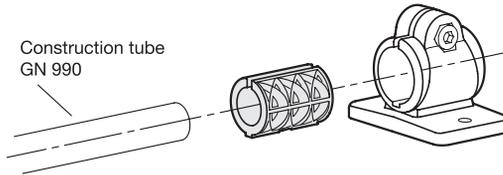

<sup>1</sup> d <sub>1</sub> Bore Clamp connector	<sup>2</sup> d <sub>2</sub> Bore					<sup>2</sup> s Square			<sup>3</sup> Length l
18	B 12	B 14	B 15	B 16	V 10	V 12			29
30	B 20	B 25	-	-	V 20	-			45

**Specification**

- Plastic, Polyamide (PA)
- Glass fiber reinforced
- Operating temperature -20 °C to +100 °C
- Color
  - Black, RAL 9005, matte finish
  - Gray, RAL 7040, matt finish
  - Blue, RAL 5005, matte finish
- FDA compliant material
- Visually detectable

- SW
- GR
- VDB

RoHS

Adapter bushings GN 290 can be used to reduce the bore diameter of plastic clamp connectors for clamping smaller diameters or square cross-sections. Due to the affixed swivel limiting stop, the adapter bushing cannot rotate or slide inside the clamp connector.

The plastic used in version VDB is made from blue, visually detectable and FDA-compliant plastic granulate as per FDA CFR.21 and EU 10/2011.

see also...	Page
GN 990 Construction Tubes (Aluminum / Stainless Steel)	QVX
GN 480.1 Retaining Square Tubes (Aluminum / Stainless Steel)	QVX

**Technical Information**

Plastic Characteristics	QVX
-------------------------	-----

How to order

<sup>1</sup> d <sub>1</sub>
<sup>2</sup> d <sub>2</sub> (s)
<sup>3</sup> Length l
<sup>4</sup> Color

**GN 290-<sup>1</sup>30-<sup>2</sup>B20-<sup>3</sup>45-<sup>4</sup>SW**

