




- 2 Type**
- A** Mounting from the back (threaded blind bore)
 - B** Mounting from the operator's side

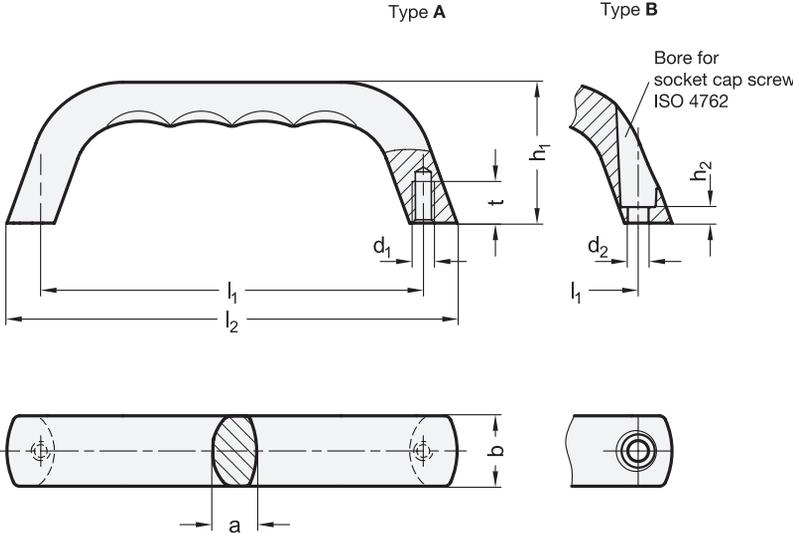

l₁	a	b	d₁ Type A	d₂ Type B	h₁	h₂	l₂	t
120	14	22	M 6	6,5	44	5	141,2	13
140	18	28	M 8	8,5	55	6	166,5	17

Specification

GN 328

Aluminum

- Powder coated
 - Black, RAL 9005, textured finish ● **SW**
 - Silver, RAL 9006, textured finish ● **SR**
- Plain finish, tumbled ○ **BL**

GN 328.5

Stainless steel precision casting AISI 316
Matte shot-blasted finish **GS**

RoHS

On request

- Other finishes

Cabinet U-handles GN 328 / GN 328.5 have excellent stability and ergonomic design. The finger recesses on the underside of the handle provide a specially comfortable grip.

In particular in combination with the larger cabinet U-handles GN 428, they meet the requirements of modern industrial design.

see also...

	Page
GN 428 Cabinet U-Handles (Aluminium)	QVX
GN 565 Cabinet U-Handles (Aluminium)	QVX

Technical Information

Load Rating Information	QVX
Stainless Steel Characteristics	QVX

How to order (Aluminum)

GN 328-120-A-SW

1 l ₁
2 Type
3 Finish

How to order (Stainless steel precision casting)

GN 328.5-120-A-GS

1 l ₁
2 Type
3 Finish