 



Bores for countersunk screw
DIN 7991



Swiveling range

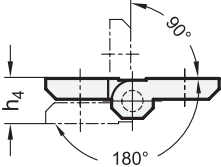

Identification no. 1



right version

Identification no. 2



left version

1

2

3

l_1	l_2	$d_1 + 0,5$	d_2	h_1	h_2	h_3	h_4	l_3	$m_1 \pm 0,25$	$m_2 \pm 0,25$
40	40	4	4	9	5	5,5	11	14	25	25
50	50	6	6	11,5	6	6,5	13	18	30	30
60	60	6	6	15	8	8,5	17	26	36	36
60	60	8	8	15	8	8,5	17	26	36	36

Specification

- Plastic (Polyamide PA-HP)
 - Glass fiber reinforced
 - Temperature resistant up to 100 °C
 - Black, matte finish
- Pin
 - Plastic (Polyamide PA)
 - Glass fiber reinforced
- Load Rating Information → Page 2126
- Plastic Characteristics → Page 2158
- RoHS

Information

- see also...
- List of Hinge Types → Page 1284 ff.
 - Hinges GN 237 (not Detachable) → Page 1292
 - Stainless Steel Spacer Plates GN 2370 → Page 1350
 - Stainless Steel Plates GN 2372 → Page 1351
 - Rubber Bumper Stops GN 2374 → Page 1298

How to order	1	l_1
	2	l_2
	3	d_1
	4	Type
	5	Identification no.
	6	Color

1

2

3

4

5

6

GN 337.1-60-60-8-A-1-SW