


Application example

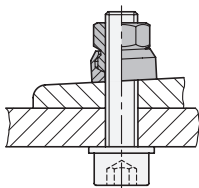

1 d₁	2 d₂	Length l ≈	A/F
17	M 8	14	13
21	M 10	17,5	16
24	M 12	21,5	18
30	M 16	28	24
36	M 20	35	30
44	M 24	42,5	36

Specification

- Steel
 - Property class 10
 - Blackened
- *Strength Values of Nuts → Page 2152*
- RoHS

Information

Hex nuts with ball socket GN 347 are capable of clamping slanting, non-parallel surfaces at an incline of up to 3°. The nut is attached to prevent loss and ensure quick, reliable and efficient assembly.

How to order	1	d ₁
	2	d ₂
GN347-30-M16		