


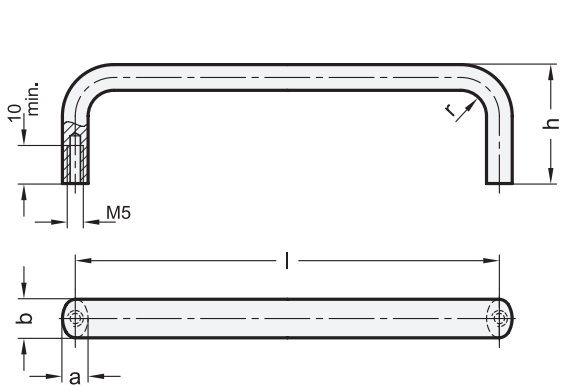

1 b	2 Length l ±0,25	a	h	r
12	55*	8	40	8
12	88*	8	40	8
12	100	8	40	8
12	120*	8	40	8
12	180*	8	40	8
12	200	8	40	8
12	235*	8	40	8

* suitable for 19" rack and enclosure layout

Specification

GN 427

Aluminum

- Powder coated
- Black, RAL 9005, textured finish
- Silver, RAL 9006, textured finish
- Anodized, natural color

GN 427

Stainless steel AISI 304

Matte shot-blasted

RoHS

3

- **SW**
- **SR**
- **EL**

Cabinet „U“ handles GN 427 / GN 427.5 are produced from profiled aluminum extrusions.	
see also...	Page
GN 425 Cabinet U-Handles (Aluminum / Stainless Steel)	QVX
Technical Information	
Load Rating Information	QVX
Stainless Steel Characteristics	QVX

How to order (Aluminum)	1 b
1 2 3 GN 427-12-120-EL	2 Length l
	3 Finish

How to order (Stainless steel)	1 b
1 2 GN 427.5-12-180	2 Length l