


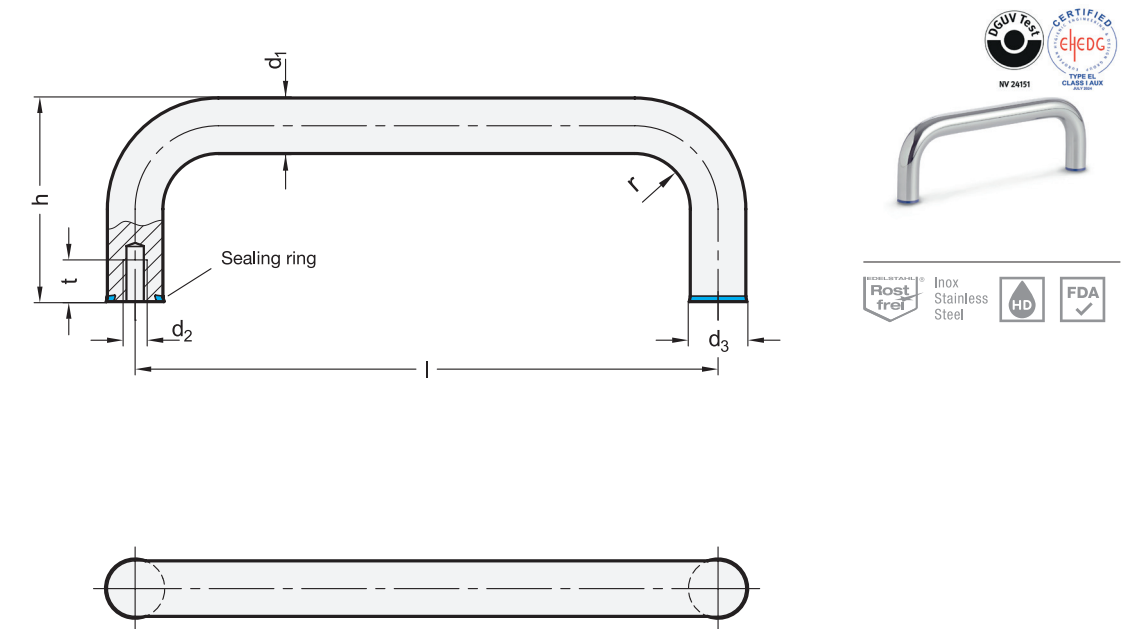

2 d₁	3 Length l ±0,5			d₂	d₃	h	r	t min.
12	125	160	200	M 5	12,8	51	14	12
16	160	200	250	M 6	16,8	59	18	12
20	200	250	300	M 8	20,8	85	22	15

Specification		1	4	5
Handle				
Stainless steel AISI 316L	A4			
• Matte finish (Ra < 0.8 µm)				
• Polished finish (Ra < 0.8 µm)	MT PL			
Sealing rings				
• H-NBR	H			
• Operating temperature -25 °C to + 150 °C				
• EPDM	E			
• Operating temperature -40 °C to + 120 °C				
• FKM	F			
• Operating temperature -5 °C to +200 °C				
• FDA compliant material				
• Blue				
• Hardness 85±5 Shore A				

RoHS

Cabinet U-handles GN 429 are intended for use in hygienic areas. The versions with PL finish comply additionally according to the guidelines of the EHEDG and DGVV Test guidelines.

The sealed mounting surfaces enable fastening without dead spaces. The high quality finish prevents adherence of dirt and facilitates cleaning.

Technical Information	Page
Product Family Hygienic Design	QVX
Load Rating Information	QVX
Plastic Characteristics	QVX
Stainless Steel Characteristics	QVX

Accessory	
GN 7600 Sealing Rings	QVX

How to order		1	Material
		2	d ₁
		3	Length l
		4	Finish
		5	Material (Sealing ring)
GN 429-A4-12-160-MT-H			