
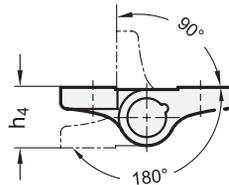


**4 Type**

**A** 2x2 bores for countersunk screws

**Swiveling range**

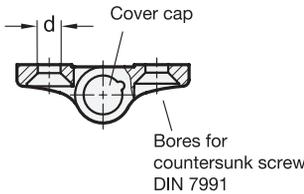

**2**

**3**

$l_1$	$l_2$	$d$	$h_1$	$h_2$	$h_3$	$h_4$	$l_3$	$m_1$	$m_2$
60	60	8,3	18,5	7,5	9,5	19	20	36	36

**Specification**

**1**

**5**

- Zinc die casting **ZD**
- Powder coated
- Black, RAL 9005, textured finish **● SW**
- Silver, RAL 9006, textured finish **● SR**
- Cover cap
- Plastic (Polyacetal POM)
- Temperature resistant up to 80 °C
- Load Rating Information → Page 2121
- Plastic Characteristics → Page 2158
- RoHS

**Accessory**

- Stainless Steel Spacer Plates GN 2370  
→ Page 1350
- Stainless Steel Plates with Tapped Holes GN 2372  
→ Page 1351

**Information**

Hinges GN 437.1 of zinc die casting fit perfectly into a wide range of environments thanks to their timeless design.

Moreover, they are matched with the GN 437 functional hinge family as complementary hinges.

see also...

- List of Hinge Types → Page 1284 ff.
- Hinges GN 437 (with Adjustable Friction) → Page 1390
- Hinges GN 437.2 (with Clamp) → Page 1396
- Hinges GN 437.3 (with Spring-Loaded Return) → Page 1398
- Hinges GN 437.4 (with Indexing Function) → Page 1393

**How to order**

<b>1</b>	Material
<b>2</b>	$l_1$
<b>3</b>	$l_2$
<b>4</b>	Type
<b>5</b>	Color

**GN 437.1-ZD-60-60-A-SR**

