


Resilient characteristics for foot disks / levelling feet

for GN 438 / GN 438.5 / GN 439 / GN 439.5

Resilient characteristics for 70° Shore
under axial and static load.

GN 439 / GN 439.5

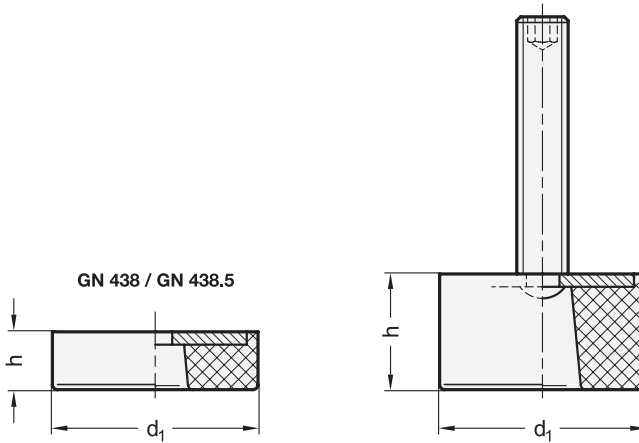

d ₁	h	Spring rate ≈ in N/mm	max. load in N	max. travel in mm
19	3	282	480	1,7
19	7	213	373	1,75
19	14	68	240	3,5
25	3	1870	1870	1
25	8	349	698	2
25	16	135	540	4
32	4	1680	1680	1
32	9	548	1233	2,25
32	18	212	850	4
38	4	1500	1500	1
38	10	704	1760	2,5
38	20	230	920	4
50	5	3600	3600	1
50	11	1223	3670	3
50	22	500	2500	5
64	5	1460	1460	1
64	13	2016	6050	3
64	26	616	3700	6

