 





Type D0





Type D1

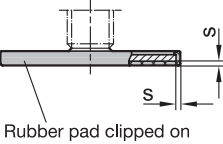

Type D3

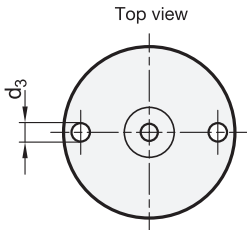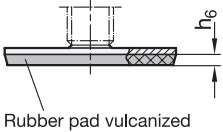

Type B0

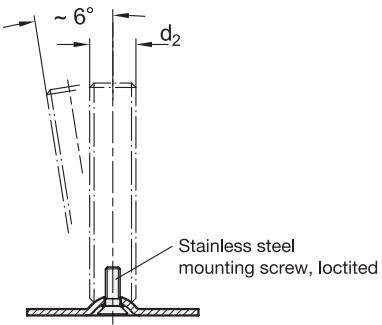 

edelstahl®
Rostfrei
Inox
Stainless
Steel



4 Type (Base plate)

- D0** Without rubber pad
- B0** Without rubber pad, with 2 fixing holes
- D1** With rubber pad, clipped on, black
- D3** With rubber pad, vulcanized, black

1	2	3																		
d ₁	d ₂	I ₁				Version S / SK							Version T / TK							
40	M 8	40	50	63	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-
40	M 10	50	60	80	100	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-
40	M 12	60	80	100	125	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-
40*	M 16	-	-	-	-	75	100	125	150	200	250	-	-	-	-	-	-	-	-	-
50	M 8	40	50	63	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-
50	M 10	50	60	80	100	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-
50	M 12	60	80	100	125	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-
50	M 16	-	-	-	-	75	100	125	150	200	250	-	-	-	-	-	-	-	-	-
60	M 8	40	50	63	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-
60	M 10	50	60	80	100	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-
60	M 12	60	80	100	125	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-
60	M 16	-	-	-	-	75	100	125	150	200	250	-	-	-	-	-	-	-	-	-
80	M 8	40	50	63	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-
80	M 10	50	60	80	100	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-
80	M 12	60	80	100	125	-	-	-	-	-	-	-	-	-	-	-	-	-	-	-
80	M 16	-	-	-	-	75	100	125	150	200	250	-	-	-	-	-	-	-	-	-
80	M 20	-	-	-	-	75	100	125	150	200	250	-	-	-	-	-	-	-	-	-
80	M 24	-	-	-	-	100	125	150	200	300	-	-	-	-	-	-	-	-	-	-

* not available in type B0

Versions of threaded stem

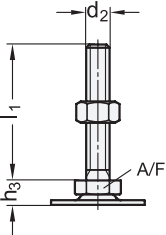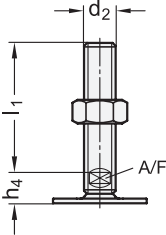 S Without nut SK With nut	 T Without nut TK With nut
External hex at the bottom at d ₂ M 8, M 10, M 12	Wrench flat at the bottom at d ₂ M 16, M 20, M 24

d ₁	d ₂			d ₃	h ₁	h ₃	h ₄	h ₆	m	s	A/F ₁	A/F ₂
40	M 8	M 10	M 12	5,4	2	11	-	3,5	30	1,5	17	-
40	M 16	-	-	5,4	2	-	17	3,5	30	1,5	-	12
50	M 8	M 10	M 12	6,6	2,5	11	-	4	38	2	17	-
50	M 16	-	-	6,6	2,5	-	17	4	38	2	-	12
60	M 8	M 10	M 12	6,6	2,5	11	-	4,5	48	2	17	-
60	M 16	-	-	6,6	2,5	-	17	4,5	48	2	-	12
80	M 8	M 10	M 12	8,5	3	12	-	5	64	2	17	-
80	M 16	-	-	8,5	3	-	18	5	64	2	-	12
80	M 20	-	-	8,5	3	-	19	5	64	2	-	15
80	M 24	-	-	8,5	3	-	22	5	64	2	-	19

Specification

- Base plate
Stainless Steel AISI 316L
Plain, ground
- Threaded stem
Stainless steel AISI 316L
- Hex nut ISO 4032
Stainless steel
- Rubber cap
 - Clipped on
 - Black, TPE (Santoprene®)
≈ 80 Shore A
- Rubber pad
 - Vulcanized
 - Black, NBR (Perbunan®)
70±5 Shore A
- Load Rating Information → Page 2145
- Plastic Characteristics → Page 2158
- Stainless Steel Characteristics → Page 2166
- RoHS

Information

Leveling feet GN 44 are for use in aggressive environments. The range of combinations of base plates and adjustable spindle versions allows these leveling feet to be used in every situation.

The base plate with the rubber pad protects sensitive surfaces and reduces lateral slippage. The type B0 can also be fastened to the mounting surface through two holes.

The leveling feet are supplied fully assembled and are not removable.

see also...

- Leveling Feet GN 40 (Steel, without Fixing Lug) → Page 1460
- Leveling Feet GN 41 (Stainless Steel, without Fixing Lug) → Page 1462
- Leveling Feet GN 42 (Steel, with Fixing Lug) → Page 1466 / 1468
- Leveling Feet GN 43 (Stainless Steel, with Fixing Lug)
→ Page 1470 / 1472
- Leveling Feet GN 45 (Stainless Steel, with Fixing Lug) → Page 1474

How to order	1	d ₁
	2	d ₂
	3	l ₁
	4	Type (Base)
	5	Version (Screw)

