


Mounting information

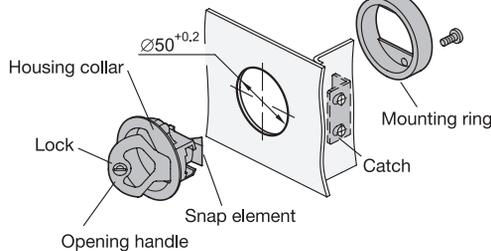

2 Type
OS Without lock
SC With lock (same lock)



1

d ₁	Wall thickness		b	d ₂	d ₃	h ₁	h ₂	h ₃	l ₁	l ₂	l ₃	l ₄ ≈	l ₅	l ₆	l ₇	l ₈	l ₉	m	w
Nominal size	s																		Adjustable range
61	A 1	1...5	32	60	5,5	36	3	16,5	6,5	16	13	8	33,5	16	18	1,2	27,5	19,5	3

Specification

Latch / Catch
 Stainless steel AISI 304
 • Housing collar / Mounting ring / Opening handle
 Polished **PL**
 • Pan head screws

Lock
 Stainless steel AISI 316

Key
 Brass, nickel plated

RoHS

Snap latches GN 449.5 combine the function of a gripping tray with that of a snap latch to provide an easy way to keep doors, covers and hoods closed. Once the mounting hole has been drilled, the housing is inserted into the hole in the door body when actuated and the mounting ring is pushed on from behind. The housing and mounting ring are connected with two supplied pan head screws.

The catch is mounted on the door profile or frame at a right angle to the snap element in accordance with the dimensions.

The snap latches of type SC are each supplied with a key. The key can be removed in both end positions. The locking mechanism is standardized so that each lock can be opened with the same key.

see also...

	Page
GN 449.1 Spring-Bolt Door Latches	QVX
GN 449.4 Snap Latches (Plastic)	QVX

Technical Information

Stainless Steel Characteristics	QVX
---------------------------------	-----

How to order

1	d ₁
2	Type
3	Finish

GN 449.5-61-OS-PL