


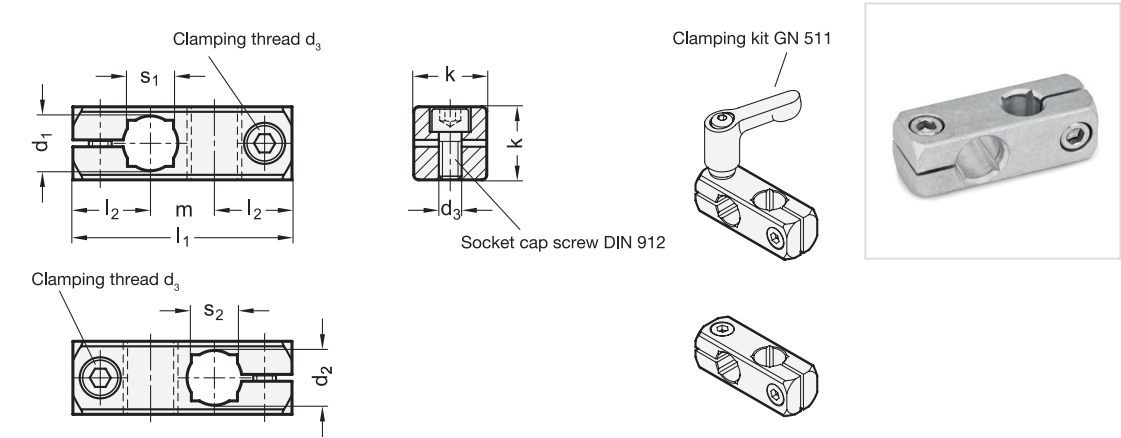

1 d₁ Bore for shaft tol. h11	2 d₂ Bore for shaft tol. h11	d₃ Clamping thread	k	l ₁	l ₂	m	s ₁	Square	s ₂	Square	Clamping kits for d ₃
B 8	B 8	M 4	14	37	13,5	10	-	-	-	-	GN 511-M4-14
B 10	B 8	M 5	16	46	17	12	8	-	-	-	GN 511-M5-16
B 10	B 10	M 5	16	46	17	12	8	8	-	-	GN 511-M5-16
B 12	B 8	M 5	16	48	17	14	10	-	-	-	GN 511-M5-16
B 12	B 12	M 5	16	48	17	14	10	10	10	10	GN 511-M5-16
B 15	B 10	M 6	20	58	20,5	17	12	8	-	-	GN 511-M6-20
B 15	B 12	M 6	20	58	20,5	17	12	10	10	10	GN 511-M6-20
B 15	B 15	M 6	20	58	20,5	17	12	12	12	12	GN 511-M6-20
B 16	B 12	M 6	20	59	20,5	18	-	10	-	-	GN 511-M6-20
B 16	B 16	M 6	20	59	20,5	18	-	-	-	-	GN 511-M6-20
B 20	B 15	M 6	25	65	21,5	22	16	12	-	-	GN 511-M6-25
B 20	B 16	M 6	25	65	21,5	22	16	-	-	-	GN 511-M6-25
B 20	B 20	M 6	25	65	21,5	22	16	16	16	16	GN 511-M6-25

Specification

- Aluminum
 - Matte finish, tumbled
 - Black anodized
- Socket cap screws DIN 912
 - Stainless steel AISI 304
- ISO Fundamental Tolerances → Page 2151
- Stainless Steel Characteristics → Page 2166
- RoHS

MT
ELS

Information

In the standard version, the clamping screws are socket cap screws with hexagonal socket DIN 912. They can be replaced by clamping kits GN 511 (article code see table of dimensions).

see also...

- Retaining Rods / Retaining Tubes GN 480.1 → Page 1833
- Two-Way Mounting Clamps GN 174 (Plastic) → Page 1808
- Swivel Clamp Connector Joints GN 490 → Page 1774
- Two-Way Connector Clamps GN 131 → Page 1718

Accessory

- Clamping Kits GN 511 → Page 1804

How to order	1	d ₁
GN 474-B12-B12-ELS	2	d ₂
	3	Finish