
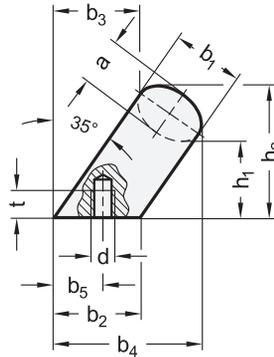


Application example

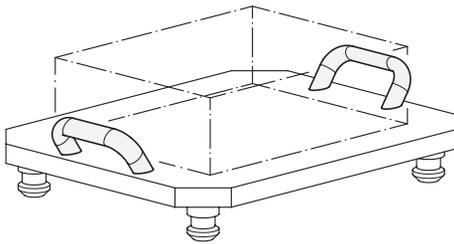

**3 Type**

**A** Mounting from the back (threaded blind bore)

1

2

b <sub>1</sub>	Length l ±0,25	a	b <sub>2</sub>	b <sub>3</sub>	b <sub>4</sub>	b <sub>5</sub> +1	d	h <sub>1</sub>	h <sub>2</sub>	r	t min.
20	112	13	24	32	50	13,5	M 6	32	48	13	10
20	128	13	24	32	50	13,5	M 6	32	48	13	10
26	128	17	32	34	57	18	M 8	34	54	17	12
26	160	17	32	34	57	18	M 8	34	54	17	12

**Specification**

4

Stainless steel AISI 304

Matte shot-blasted finish

MT

RoHS

Inclined stainless steel cabinet U-handles GN 565.7 are manufactured from a bent stainless steel profile. Their special features are their rigidity and ergonomical shaping.

The angled contact surface allows improved access even in tight spaces such as corners.

see also...

Page

**GN 565.2** Inclined Cabinet U-handles (Aluminum, Mounting from the Back or the Operator's Side) QVX

**GN 425.1** Cabinet U-Handles (Aluminum / Stainless Steel, angled) QVX

**GN 426.6** Cabinet U-Handles (angled) QVX

**Technical Information**

Load Rating Information QVX

Stainless Steel Characteristics QVX

How to order

**GN 565.7-20-128-A-MT**

- 1 b<sub>1</sub>
- 2 Length l
- 3 Type
- 4 Finish