


Application example

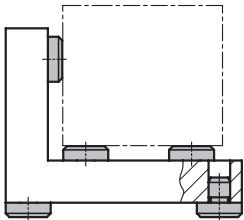

1 d_1 g6	2 h h9	d_2 n6	Length l
6	2,5	4	6,5
6	4,5	4	8,5
6	5	4	6
10	4,5	6	8,5
10	8	6	8
16	5	8	10
16	13	8	10
20	6	10	12
20	12	10	12
25	8	12	14
25	20	12	14
25	30	12	14
30	25	16	20
30	40	16	20
30	50	16	20
30	65	16	20
40	13	20	20
40	32	20	20

Specification

- Steel
Hardened
- ISO Fundamental Tolerances → Page 2151
- RoHS

Information

Headed dowels GN 6321.1 can also be used as feet and supports.
[see also...](#)
• Headed Dowels DIN 6321 → Page 1116

How to order

1

2

GN6321.1-25-8

1	d_1
2	h