


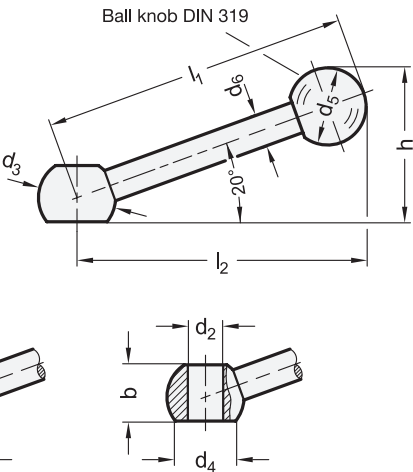

- 3 Type**
- L** Angled lever with plain bore
 - N** Angled lever with threaded bore

1 l_1	2 d_1 Thread	2 d_2 H7 Bore	b	d_3	d_4	d_5	d_6	$h \approx$	$l_2 \approx$
63	M 8	B 8	12	16	12,5	20	8	33	60
80	M 10	B 10	14,5	20	16	20	9	40	76
100	M 12	B 12	18,5	25	20	25	11	50	95
125	M 16	B 16	24	32	25	32	15	63	119
160	M 20	B 20	30	40	31	40	18	80	152

Specification

Hub / Shaft

- Steel
- Turned
- Blackened

Ball knobs DIN 319

- Plastic, phenolic resin (PF)
- Black

RoHS

The official DIN standard sheet specifies additional sizes 200 - M24 / B24.

see also...	Page
GN 6337.3 Adjustable Clamping Levers	QVX
DIN 99 Clamping Levers	QVX
GN 212 Tension Levers	QVX

Technical Information

ISO Fundamental Tolerances	QVX
----------------------------	-----

How to order	1 l_1
	2 d_1 (d_2)
	3 Type
DIN 6337-100-M12-N	