
 
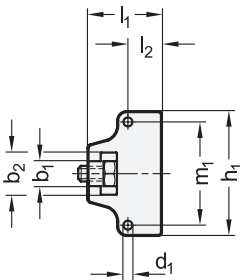


Identification no. 1



Identification no. 2

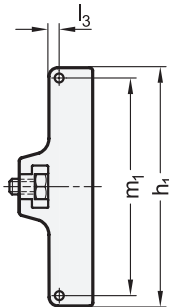


elesa
Original design TGL




1 Identification no.

- 1 Single row
2 Double row

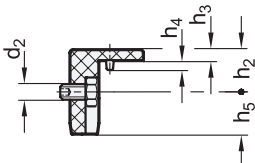

Application example

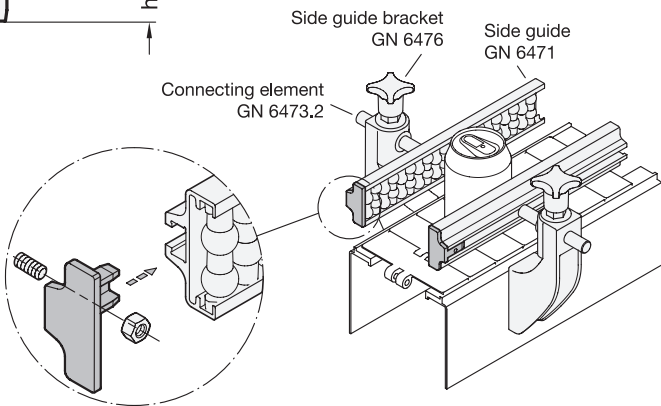

2

l_1	b_1	b_2	d_1	d_2	h_1	Id. no. 1	Id. no. 2	h_2	h_3	h_4	h_5	l_2	l_3	m_1	Id. no. 1	Id. no. 2
24	8	13,5	2,5	M 5	47,5	93		13,5	3,5	3	13,5	10,8	3,2	40,9		86

Specification

End cap

Plastic, polyamide PA
• Operating temperature -30 °C to +100 °C
• Gray GR

Grub screw / nut

Stainless steel AISI 304

RoHS

End caps GN 6471.2 extend side guides GN 6471. They ensure an attractive appearance and protect against injuries or damage to the conveyed goods. They are mounted on the end face by sliding into the T-slot of the side guide using the supplied grub screw.

see also...

GN 6471 Side Guides	QVX
GN 6476 Side Guide Brackets	QVX
GN 6473.2 Connecting Elements	QVX

Technical Information

Plastic Characteristics	QVX
Stainless Steel Characteristics	QVX

How to order	1 Identification no.
	2 l_1
	3 Material
	4 Color
GN6471.2-2-24-PA-GR	