


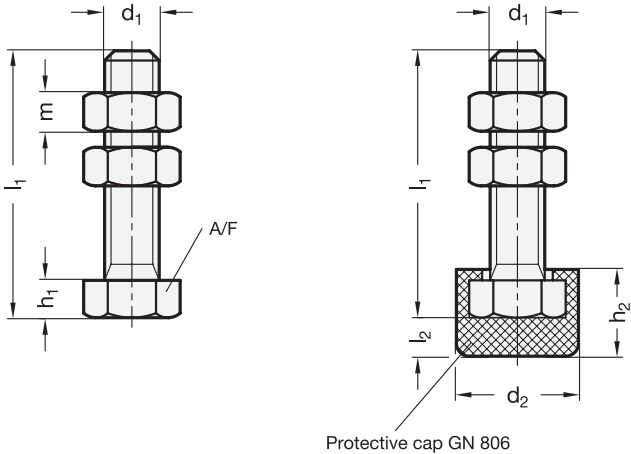

- 3Type
- A

Without protective cap
- B

With protective cap

d ₁		l ₁			d ₂	h ₁	h ₂	l ₂	m	A/F
Steel	Stainless Steel									
M 4	M 4	23	-	-	11	3	6,5	2,5	3,2	7
M 5	M 5	38	-	-	12,5	3,5	8	2,5	4,7	8
M 6	M 6	29	49	-	15	4	10	4	5,2	10
M 8	M 8	36	56	96	19	5,5	13	5,5	6,8	13
M 10	-	43	77	127	24	6,5	16	7	8,4	16
M 12	-	53	88	128	26	7,5	19	8,5	10,8	18
M 14*	-	54	-	-	-	9	-	-	12,8	21

* Clamping screw M14 is not available as type B (with protective cap)

Specification

- 4

• Steel

—

- Hex head screw

ISO 4017 / DIN 933

Property class 8.8

Zinc plated, blue passivated

- Hex nuts ISO 4032

Zinc plated, blue passivated

• Stainless steel AISI 304

NI

- Hex head screw ISO 4017 / DIN 933

- Hex nuts ISO 4032

• Protective Caps GN 806 → Page 1533

• Stainless Steel Characteristics → Page 2166

• RoHS

Information

- The two hex nuts are included parts of the order.
- see also...
- Holders for Clamping Screws GN 801

(for Toggle Clamps with Forked Clamping Arm) → Page 815

How to order (Steel)	1	d ₁
	2	l ₁
	3	Type
GN 807-M8-56-B		

How to order (Stainless steel)	1	d ₁
	2	l ₁
	3	Type
	4	Material
GN 807-M6-29-A-NI		