


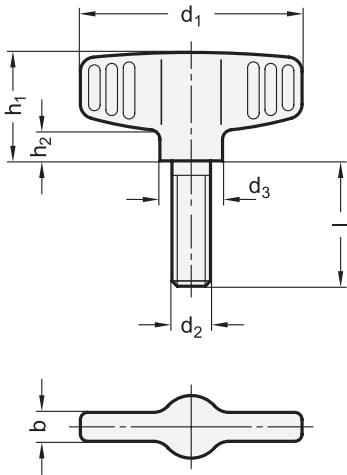

 **Rostfrei**
Inox
Stainless
Steel

1 d₁	2 d₂	3 Length l	d₃	b	h₁	h₂
46	M 6	162025	13	6	22,5	6
46	M 8	162025	13	6	22,5	6
58	M 8	202530	16	7	26,5	7
58	M 10	202530	16	7	26,5	7

Specification

- Stainless steel
- Precision casting AISI CF-8
- Matte shot-blasted
- Stainless Steel Characteristics → Page 2166
- RoHS

4

Information

- see also...
- Stainless Steel Wing Screws GN 431 → Page 621
 - Stainless Steel Wing Screws GN 433 → Page 620
 - Stainless Steel Hand Knobs GN 6335.5 → Page 583

How to order		1	d ₁
		2	d ₂
		3	Length l
		4	Finish
GN 835-58-M10-25-MT			