


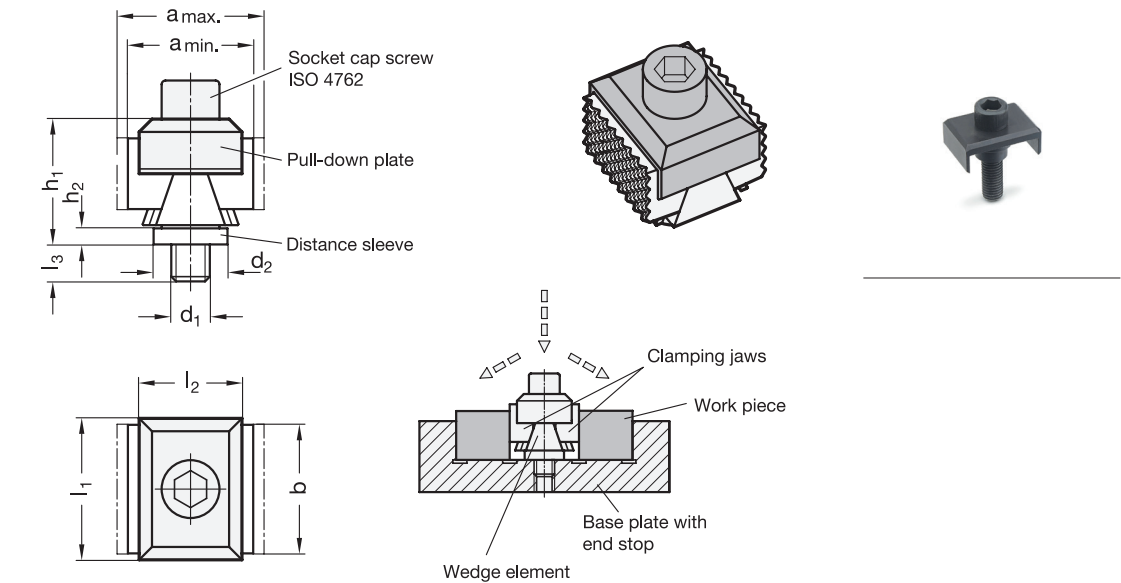

1 l ₁	2 l ₂	3 d ₁	a		Type RF		b	d ₂ Ø	h ₁ ≈	h ₂	Length l ₃ max.	for wedge clamps GN 920.1 with:	
			Type GA / Type GL max. min.		max. min.							d	b
25	32	M 8	44,5 39,5		39,5 34,5		21	18	27,5	4	7,5	M 8	21
29	32	M 8	44,5 39,5		39,5 34,5		25	18	27,5	4	7,5	M 8	25
36	32	M 8	44,5 39,5		39,5 34,5		32	18	27,5	4	7,5	M 8	32
44	32	M 8	44,5 39,5		39,5 34,5		40	18	27,5	4	7,5	M 8	40
44	32	M 12	45,5 40		45,5 40		40	23	38	5	11,5	M 12	40
54	32	M 8	44,5 39,5		39,5 34,5		50	18	27,5	4	7,5	M 8	50
54	32	M 12	45,5 40		45,5 40		50	23	38	5	11,5	M 12	50

Specification

Plate

Steel
Blackened

Socket cap screw ISO 4762

Steel

Distance sleeve

Steel

RoHS

Pull-down plates GN 920.2 allow wedge clamps GN 920.1 to clamp easily with pull-down effect.
The socket cap screw ISO 4762 and the distance sleeve are included.

see also...
GN 920.1 Wedge Clamps

Page
QVX

How to order	1	l ₁
	2	l ₂
	3	d ₁
GN 920.2-36-32-M8		