



Type A

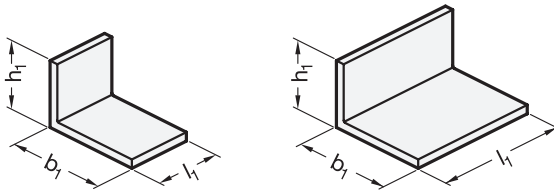

Type C

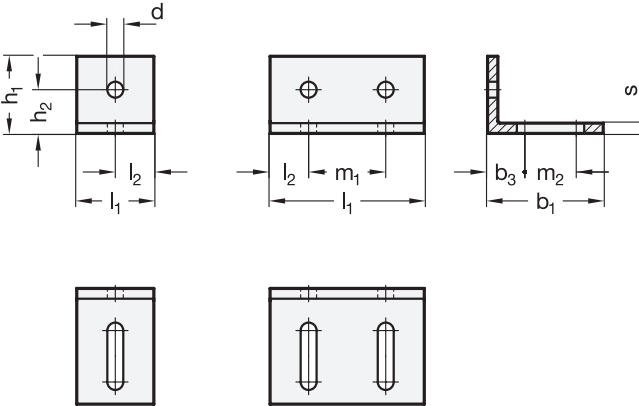

5 Type

- A Without bores
- C With bores and slotted holes

2

3

4

h_1		b_1	l_1	b_3	d	h_2	l_2	m_1	m_2	s
ALM	STB									
30	30	45	30	18	6,2	18	15	-	20	4
30	30	45	60	18	6,2	18	15	30	20	4
40	40	60	40	24	8,2	24	20	-	25	5
40	40	60	80	24	8,2	24	20	40	25	5
50	-	75	50	30	10,2	30	25	-	30	6
50	-	75	100	30	10,2	30	25	50	30	6

Specification

- Structural steel
Drawn, with sharp edges
Blackened
- Aluminum
Pressed
Matte finish, tumbled
- RoHS

1

Information

STB

Installation brackets GN 970 are used universally for right-angle connecting and fastening of, e.g. base plates or covers.

ALM

Type A allows for the use of drilling templates specific to the application as well as fastening by welding.

Type C installation brackets have one or two combinations of a hole and an elongated hole depending on the length l_1 .

see also...

- Angle Pieces, Shackles GN 967 → Page 1827

How to order

1	Material
2	h_1
3	b_1
4	l_1
5	Type

GN970-STB-40-60-80-C